
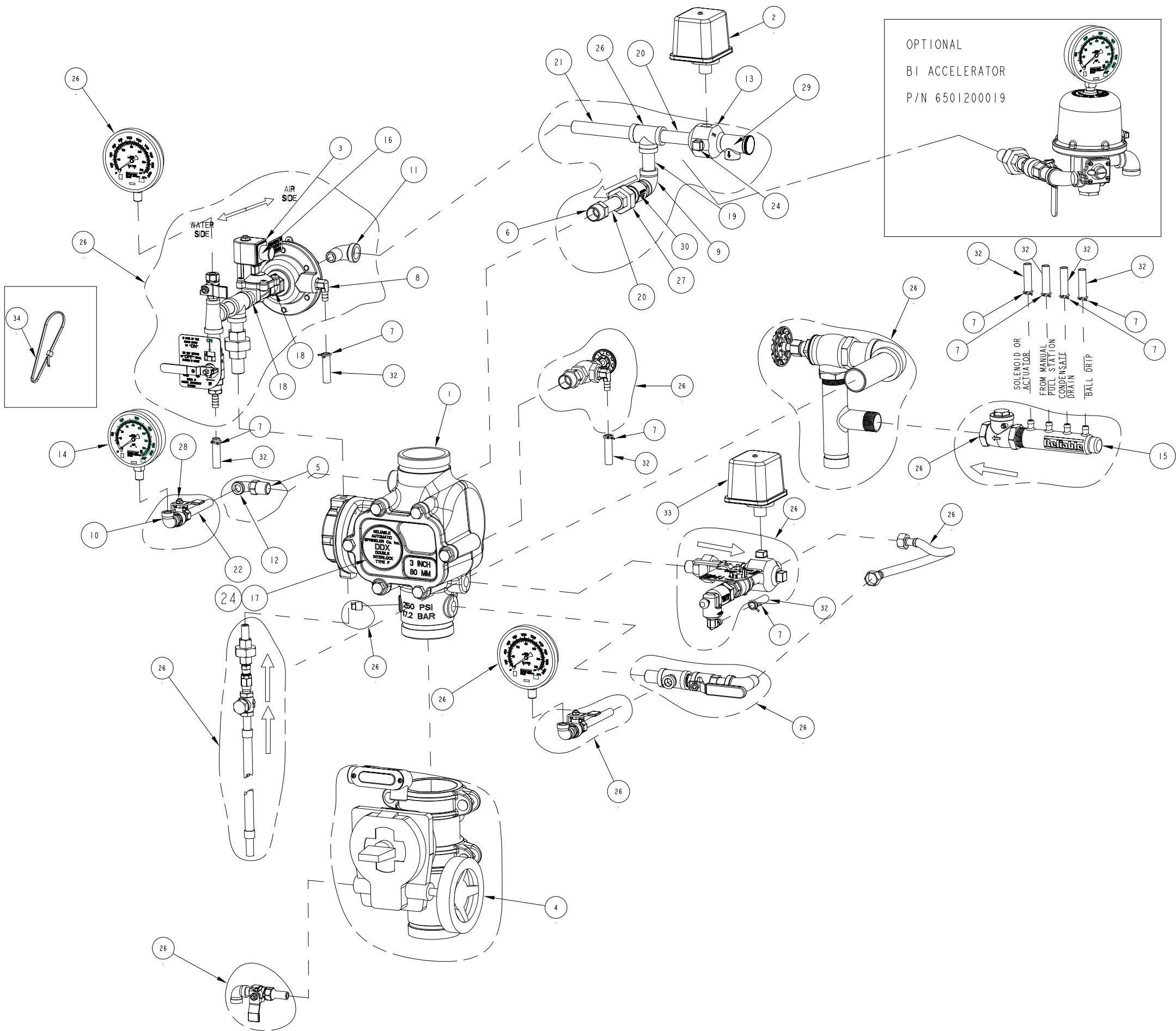


DDX VALVE TRIMS PART NUMBER CONFIGURATION

SELECTIONS IN **BOLD** ARE STANDARD OPTIONS

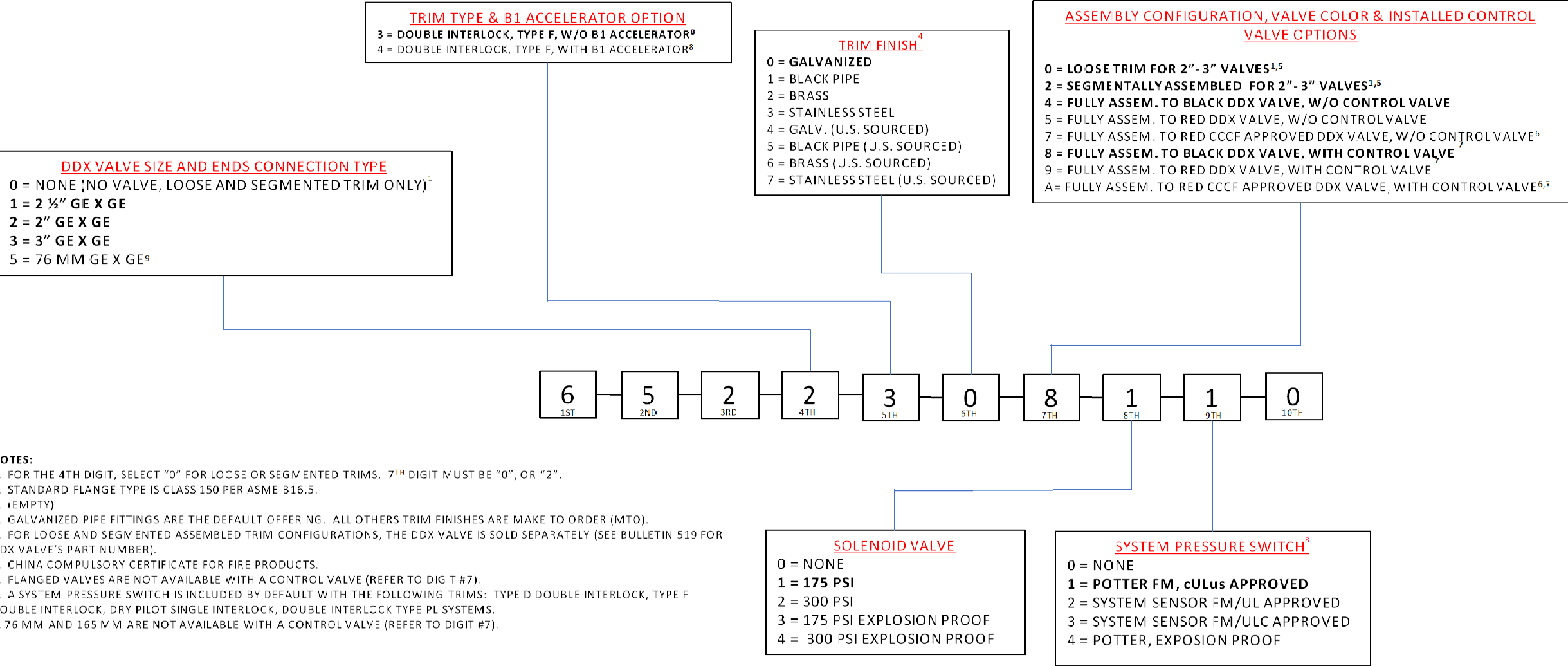


DDX VALVE PART NUMBER TABLE

DDX. VALVE	VALVE PART NUMBER	DRAWING FILE NUMBER
2" DUCTILE IRON G/G BLACK	6103022000	6103030000
2" DUCTILE IRON G/G RED	6103022001	
2-1/2" DUCTILE IRON G/G BLACK	6103022500	
2-1/2" DUCTILE IRON G/G RED	6103022501	
3" DUCTILE IRON G/G BLACK	6103030000	
3" DUCTILE IRON G/G RED	6103030001	
76MM DUCTILE IRON G/G RED	6103027600	

MODEL DDX 2"-3" DELUGE DOUBLE INTERLOCK TYPE F
CA-191 P/N 89241153 REV. G

34	89141112	TIE, RETAINING		9
33	6990012997	SWITCH, POTTER PRESSURE (PS10-EX)	(ULC, UL, FM)	1
	6990006382	SWITCH, POTTER PRESSURE (PS10-2)	(ULC, UL, FM)	
	6999992360	SWITCH, PRESSURE (EPSA10-2)	(ULC)	
	6999991212	SWITCH, PRESSURE (EPS10-2)	(UL/FM)	
32	96686756	TUBING, PVC, 3/8" I.D. x 6 FT.		1
31	95516915	PERMA-LOK		A/R
30	96816906	VALVE, CHECK, MALE 1/2", MALE 1/2"		1
29	98840228	VALVE, RELIEF, 1/2", 50 PSI		1
28	98840237	VALVE, BALL, 1/4" NPTF x 1/4" NPTM		1
27	98815204	UNION, ORING SEAL, GALV., 1/2"		1
26	98761651	TEE, 1/2X1/2X1/2, GALVANIZED	SEE CA-322 P/N 89241292	1
25	77000263	SUB-ASSEMBLY, TRIM, BASE, GALVANIZED PIPE		1
24	98604406	PIPE, PLUG, IRON, SQUARE HEAD, 1/2"		1
23	99080002	PAD-ADHESIVE, VALVE NAME PLATES		1
22	98543243	NIPPLE, 1/4X4, GALVANIZED STEEL		1
21	98543219	NIPPLE, 1/2X5, GALVANIZED STEEL		1
20	98543230	NIPPLE, 1/2X3, GALVANIZED STEEL		2
19	98543209	NIPPLE, 1/2X2, GALVANIZED STEEL		1
18	98543223	NIPPLE, 1/2X1-1/2, GALVANIZED STEEL		2
17	94616919	NAMEPLATE, DOUBLE INTERLOCK, TYPE F		1
16	71030010	MODEL LP PILOT LINE ACTUATOR		1
15	91004294	MANIFOLD, DRAIN, BARBED		1
14	98248000	GAUGE, AIR PRESSURE (0-80 PSI)		1
13	98751004	FITTING, MULTI-PORT, 1/2x1/2x1/2x1/2		1
12	98174408	ELBOW, STREET, 1/4", GALV.		1
11	98174400	ELBOW, STREET, 1/2", GALV.		1
10	98174404	ELBOW, 1/4", MALL IRON, GALV.		1
9	98174401	ELBOW, 1/2", MALL IRON, GALV.		1
8	92056704	CONNECTOR, ELBOW, 3/8" ID TUBE x 1/2" NPT		1
7	95306255	CLAMP, HOSE, 1/2" CONSTANT TENSION, ZINC		8
6	98048022	BUSHING, REDUCER, 3/4X1/2, GALVANIZED		1
5	98048000	BUSHING, REDUCER, 1/2X1/4, GALVANIZED		1
4	77000253	SUBASSEMBLY, CONTROL VALVE, 3"	FULLY ASSEMBLED WITH CONTROL VALVE ONLY	1
	77000251	SUBASSEMBLY, CONTROL VALVE, 2-1/2"		
	77000252	SUBASSEMBLY, CONTROL VALVE, 2"		
	6871020033	VALVE, SOLENOID (300 PSI) EXPLOSION PROOF	300 PSI EX. PROOF	
3	6999999322	VALVE, SOLENOID (175 PSI) EXPLOSION PROOF	175 PSI EX. PROOF	1
	6871020020	VALVE, SOLENOID (300 PSI)	300 PSI RATED	
	6871020000	VALVE, SOLENOID (175 PSI)	175 PSI RATED	
	6990003756	SWITCH, POTTER PRESSURE (PS40-EX)	(ULC, UL, FM)	
2	6990019313	SWITCH, POTTER PRESSURE (PS25-2)	(ULC, UL, FM)	1
	6999992361	SWITCH, PRESSURE (EPSA40-2)	(ULC)	
	6999991340	SWITCH, PRESSURE (EPS40-2)	(UL/FM)	
	6103022000	ASSEMBLY, VALVE, 2"		
1	6103022500	ASSEMBLY, VALVE, 2-1/2"		1
	6103030000	ASSEMBLY, VALVE, 3"		
	6103027600	ASSEMBLY, VALVE, 76MM		
ITEM NO	PART NO	DESCRIPTION		QTY.
BILL OF MATERIALS				

CA-322 P/N 89241292 REV. B

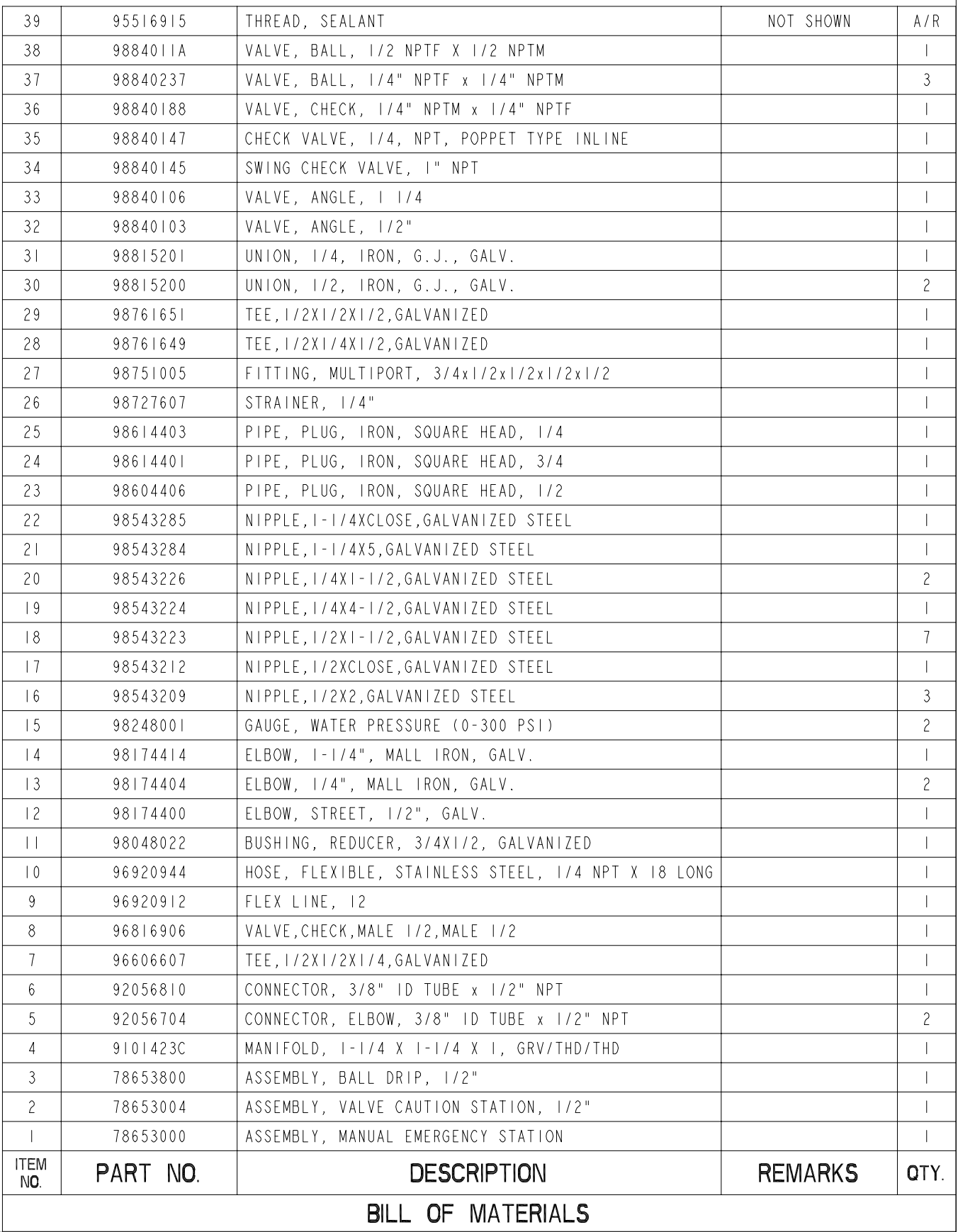

DDX VALVE TRIMS PART NUMBER CONFIGURATION

SELECTIONS IN **BOLD>** ARE STANDARD OPTIONS

DDX VALVE SIZE AND ENDS CONNECTION TYPE

0 = NONE (NO VALVE, LOOSE AND SEGMENTED TRIM ONLY)¹
4 = **4" GE X GE**
6 = **6" GE X GE**
7 = 165 MM GE X GE⁹
8 = **8" GE X GE**
A = **4" FLANGE^{2,7} INLET X GE OUTLET**
B = **4" FLANGE^{2,7} INLET X FLANGE^{2,7} OUTLET**
C = 4" PN16 FLANGE^{2,7} INLET X GE OUTLET
D = 4" PN16 FLANGE^{2,7} INLET X PN16 FLANGE^{2,7} OUTLET
E = **6" FLANGE^{2,7} INLET X GE OUTLET**
F = **6" FLANGE^{2,7} INLET X FLANGE^{2,7} OUTLET**
G = 6" PN16 FLANGE^{2,7} INLET X GE OUTLET
H = 6" PN16 FLANGE^{2,7} INLET X PN16 FLANGE^{2,7} OUTLET
I = 165 MM FLANGE^{2,7} INLET X GE OUTLET
J = 165 MM PN16 FLANGE^{2,7} INLET X GE OUTLET
K = **8" FLANGE^{2,7} INLET X FLANGE^{2,7} OUTLET**
L = 8" PN16 FLANGE^{2,7} INLET X PN16 FLANGE^{2,7} OUTLET

TRIM TYPE & B1 ACCELERATOR OPTION

3 = DOUBLE INTERLOCK, TYPE F, W/O B1 ACCELERATOR⁸
4 = DOUBLE INTERLOCK, TYPE F, WITH B1 ACCELERATOR⁸

TRIM FINISH⁴

0 = GALVANIZED
1 = BLACK PIPE
2 = BRASS
3 = STAINLESS STEEL
4 = GALV. (U.S. SOURCED)
5 = BLACK PIPE (U.S. SOURCED)
6 = BRASS (U.S. SOURCED)
7 = STAINLESS STEEL (U.S. SOURCED)

ASSEMBLY CONFIGURATION, VALVE COLOR & INSTALLED CONTROL VALVE OPTIONS

1 = LOOSE TRIM FOR 4"-8" VALVES^{1,5}
3 = SEGMENTALLY ASSEMBLED FOR 4"-8" VALVES^{1,5}
4 = FULLY ASSEM. TO BLACK DDX VALVE, W/O CONTROL VALVE
5 = FULLY ASSEM. TO RED DDX VALVE, W/O CONTROL VALVE
7 = FULLY ASSEM. TO RED CCCF APPROVED DDX VALVE, W/O CONTROL VALVE⁶
8 = FULLY ASSEM. TO BLACK DDX VALVE, WITH CONTROL VALVE
9 = FULLY ASSEM. TO RED DDX VALVE, WITH CONTROL VALVE
A = FULLY ASSEM. TO RED CCCF APPROVED DDX VALVE, WITH CONTROL VALVE^{6,7}

SOLENOID VALVE

0 = NONE
1 = 175 PSI
2 = 300 PSI
3 = 175 PSI EXPLOSION PROOF
4 = 300 PSI EXPLOSION PROOF

SYSTEM PRESSURE SWITCH⁸

0 = NONE
1 = POTTER FM, cULus APPROVED
2 = SYSTEM SENSOR FM/UL APPROVED
3 = SYSTEM SENSOR FM/ULC APPROVED
4 = POTTER, EXPLOSION PROOF

NOTES:


- FOR THE 4TH DIGIT, SELECT "0" FOR LOOSE OR SEGMENTED TRIMS. 7TH DIGIT MUST BE "1", OR "3."
- STANDARD FLANGE TYPE IS CLASS 150 PER ASME B16.5.
- (EMPTY)
- GALVANIZED PIPE FITTINGS ARE THE DEFAULT OFFERING. ALL OTHERS TRIM FINISHES ARE MAKE TO ORDER (MTO).
- FOR LOOSE AND SEGMENTED ASSEMBLED TRIM CONFIGURATIONS, THE DDX VALVE IS SOLD SEPARATELY (SEE BULLETIN 519 FOR DDX VALVE'S PART NUMBER).
- CHINA COMPULSORY CERTIFICATE FOR FIRE PRODUCTS.
- FLANGED VALVES ARE NOT AVAILABLE WITH A CONTROL VALVE (REFER TO DIGIT #7).
- A SYSTEM PRESSURE SWITCH IS INCLUDED BY DEFAULT WITH THE FOLLOWING TRIMS: TYPE D DOUBLE INTERLOCK, TYPE F DOUBLE INTERLOCK, DRY PILOT SINGLE INTERLOCK, DOUBLE INTERLOCK TYPE PL SYSTEMS.
- 76 MM AND 165 MM ARE NOT AVAILABLE WITH A CONTROL VALVE (REFER TO DIGIT #7).

DDX VALVE PART NUMBER TABLE




DDX. VALVE	VALVE PART NUMBER	DRAWING FILE NUMBER
4" DUCTILE IRON G/G BLACK	6103040026	6103040026
4" DUCTILE IRON G/G RED	6103040030	
4" DUCTILE IRON F/G CLASS 150 BLACK	6103040044	
4" DUCTILE IRON F/G CLASS 150 RED	6103040046	
4" DUCTILE IRON F/G PN16 RED	6103040048	
4" DUCTILE IRON F/F CLASS 150 BLACK	6103040045	
4" DUCTILE IRON F/F CLASS 150 RED	6103040047	6103060024
4" DUCTILE IRON F/F PN16 RED	6103040049	
6" DUCTILE IRON G/G BLACK	6103060024	
6" DUCTILE IRON G/G RED	6103060030	
6" DUCTILE IRON F/G CLASS 150 BLACK	6103060045	
6" DUCTILE IRON F/G CLASS 150 RED	6103060048	
6" DUCTILE IRON F/G PN16 RED	6103060049	6103060024
6" DUCTILE IRON F/F CLASS 150 BLACK	6103060046	
6" DUCTILE IRON F/F CLASS 150 RED	6103060047	
6" DUCTILE IRON F/F PN16 RED	6103060050	
165MM DUCTILE IRON G/G RED	6103060028	
165MM DUCTILE IRON F/G CLASS 150 RED	6103060051	
165MM DUCTILE IRON F/G PN16 RED	6103060052	6103080001
8" DUCTILE IRON G/G BLACK	6103080001	
8" DUCTILE IRON G/G RED	6103080003	
8" DUCTILE IRON F/F CLASS 150 BLACK	6103080016	
8" DUCTILE IRON F/F CLASS 150 RED	6103080018	6103080001
8" DUCTILE IRON F/F PN16 RED	6103080020	

MODEL DDX 4", 6" & 8" DELUGE DOUBLE INTERLOCK TYPE F

CA-149 P/N 89241114 REV. N

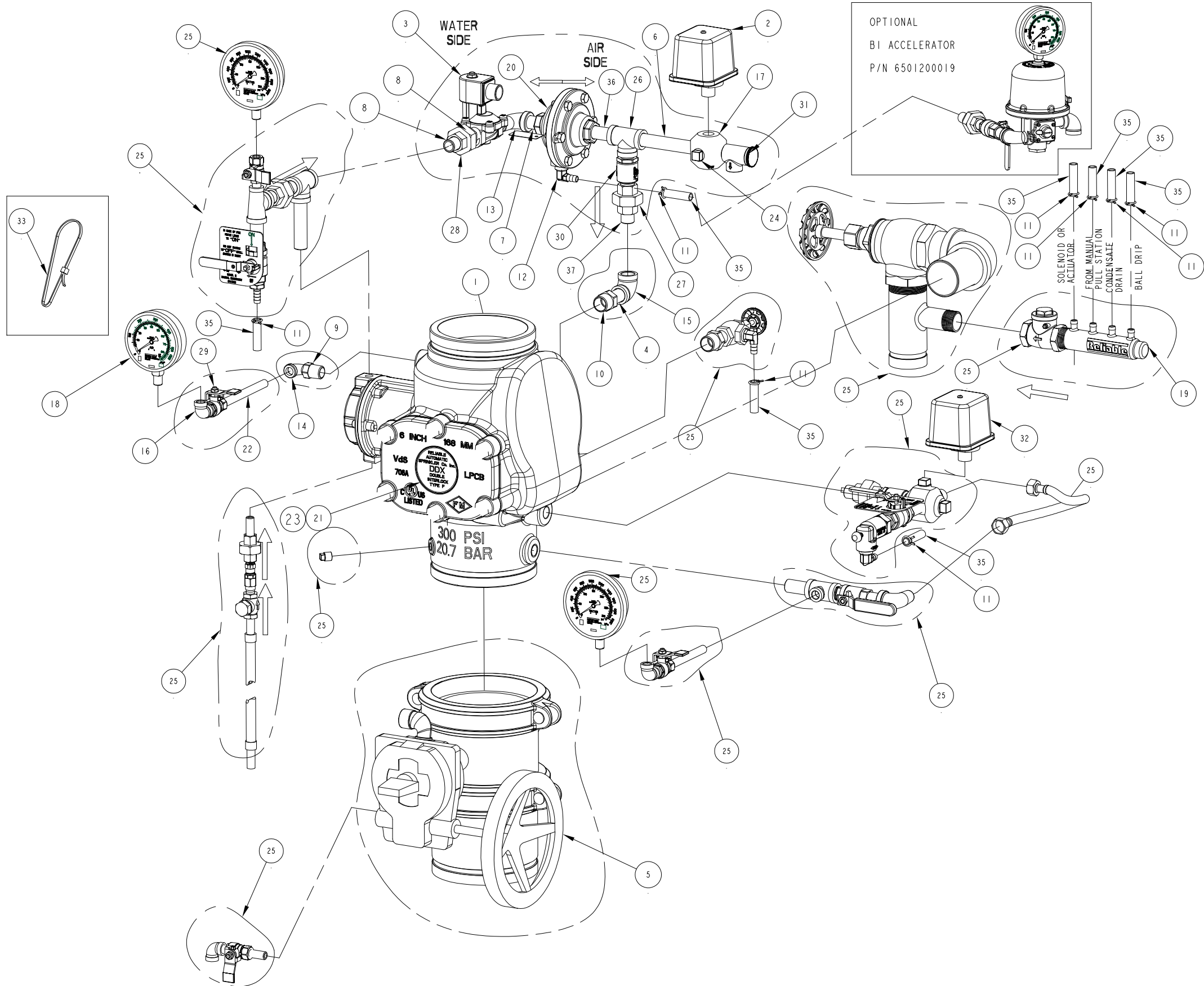




37	98543212	NIPPLE, STEEL, GALV., 1/2" X CLOSE*		I
36	98543209	NIPPLE, STEEL, GALV., 1/2" X 2"	4" & 6" VERSIONS	I
	98543230	NIPPLE, STEEL, GALV., 1/2" X 3"	8" VERSION	I
35	96686756	TUBING, PVC, 3/8" I.D. x 6 FT.		I
34	95516915	PERMA-LOK		A/R
33	89141112	TIE, RETAINING		9
	6990012997	SWITCH, POTTER PRESSURE (PS10-EX)	(ULC, UL, FM)	I
	6990006382	SWITCH, POTTER PRESSURE (PS10-2)	(ULC, UL, FM)	
	6999992360	SWITCH, PRESSURE (EPSA10-2)	(ULC)	
	6999991212	SWITCH, PRESSURE (EPS10-2)	(UL/FM)	
31	98840228	VALVE, RELIEF, 1/2", 50 PSI		I
30	96816906	VALVE, CHECK, MALE 1/2, MALE 1/2		I
29	98840237	VALVE, BALL, 1/4" NPTF x 1/4" NPTM		I
28	98815200	UNION, 1/2, IRON, G.J., GALV.		I
27	98815204	UNION, ORING SEAL, GALV., 1/2		I
26	98761651	TEE, 1/2X1/2X1/2, GALVANIZED		I
25	77000266	SUB-ASSEMBLY, TRIM, BASE, GALVANIZED PIPE	SEE CA-323 P/N 89241293	I
24	98604406	PIPE, PLUG, IRON, SQUARE HEAD, 1/2		I
23	99080002	PAD-ADHESIVE, VALVE NAME PLATES		I
22	98543217	NIPPLE, 1/4X6, GALVANIZED STEEL		I
21	94616919	NAMEPLATE, DOUBLE INTERLOCK, TYPE F		I
20	71030010	MODEL LP PILOT LINE ACTUATOR		I
19	91004294	MANIFOLD, DRAIN, BARBED		I
18	98248000	GAUGE, AIR PRESSURE (0-80 PSI)		I
17	98751004	FITTING, MULTIPORT, 1/2x1/2x1/2x1/2		I
16	98174404	ELBOW, 1/4", MALL IRON, GALV.		I
15	98174401	ELBOW, 1/2", MALL IRON, GALV.		I
14	98174408	ELBOW, STREET, 1/4", GALV.		I
13	98174400	ELBOW, STREET, 1/2", GALV.		I
12	92056704	CONNECTOR, ELBOW, 3/8" ID TUBE x 1/2" NPT		I
11	95306255	CLAMP, HOSE, 1/2" CONSTANT TENSION, ZINC		8
10	98048022	BUSHING, REDUCER, 3/4X1/2, GALVANIZED		I
9	98048000	BUSHING, REDUCER, 1/2X1/4, GALVANIZED		I
	98543212	NIPPLE, STEEL, GALV., 1/2" X CLOSE	4" & 6" VERSIONS	2
	98543223	NIPPLE, STEEL, GALV., 1/2" X 1-1/2"	8" VERSION	
7	98543223	NIPPLE, STEEL, GALV., 1/2" X 1-1/2"		2
	98543230	NIPPLE, STEEL, GALV., 1/2" X 3"	4" VERSION	
	98543228	NIPPLE, STEEL, GALV., 1/2" X 4-1/2"	6" VERSION	I
	98543204	NIPPLE, STEEL, GALV., 1/2" X 6"	8" VERSION	
	77000258	SUBASSEMBLY, CONTROL VALVE, 8"	FULLY ASSEMBLED WITH CONTROL VALVE ONLY	I
	77000256	SUBASSEMBLY, CONTROL VALVE, 6"		
	77000254	SUBASSEMBLY, CONTROL VALVE, 4"		
	98543210	NIPPLE, STEEL, GALV., 1/2" X 2-1/2"	4" VERSION	
4	98543209	NIPPLE, STEEL, GALV., 1/2" X 2"	6"-8" VERSIONS	I
	6871020033	VALVE, SOLENOID (300 PSI) EXPLOSION PROOF	300 PSI EX. PROOF	
	6999990322	VALVE, SOLENOID (175 PSI) EXPLOSION PROOF	175 PSI EX. PROOF	I
	6871020020	VALVE, SOLENOID (300 PSI)	300 PSI RATED	
	6871020000	VALVE, SOLENOID (175 PSI)	175 PSI RATED	I
	6990003756	SWITCH, POTTER PRESSURE (PS40-EX)	(ULC, UL, FM)	
	6990019313	SWITCH, POTTER PRESSURE (PS25-2)	(ULC, UL, FM)	
	6999992361	SWITCH, PRESSURE (EPSA40-2)	(ULC)	
	6999991340	SWITCH, PRESSURE (EPS40-2)	(UL/FM)	
	SEE TRIMS PART NUMBER CONFIGURATION	ASSEMBLY, VALVE, 8" (200MM)		I
		ASSEMBLY, VALVE, 4" (100MM)		
		ASSEMBLY, VALVE, 6" (150MM)		
		ASSEMBLY, VALVE, 165MM		
ITEM NO.	PART NO.	DESCRIPTION	REMARKS	QTY.
BILL OF MATERIALS				

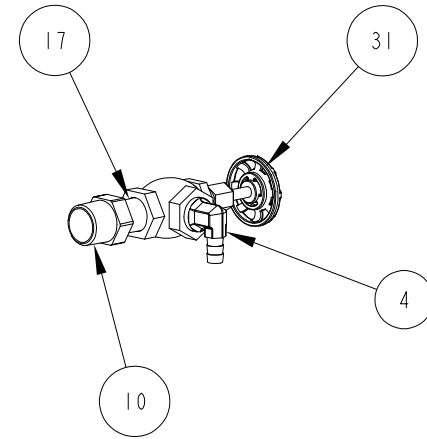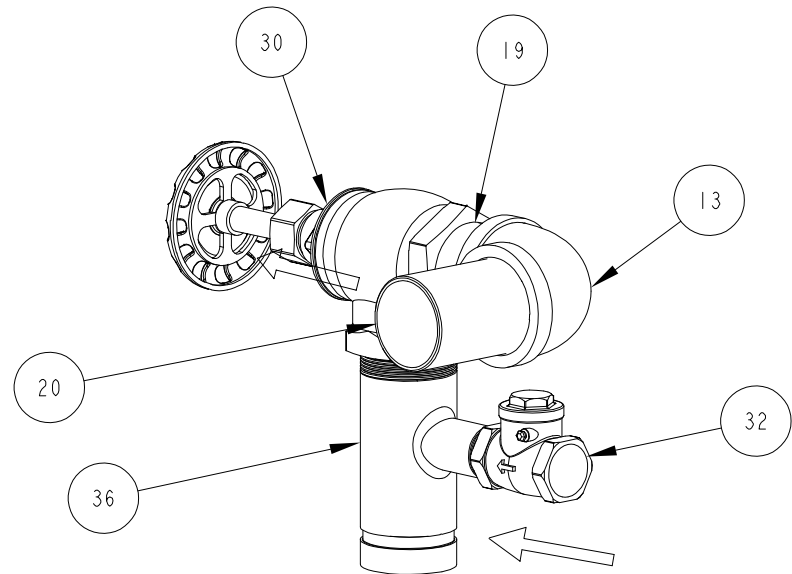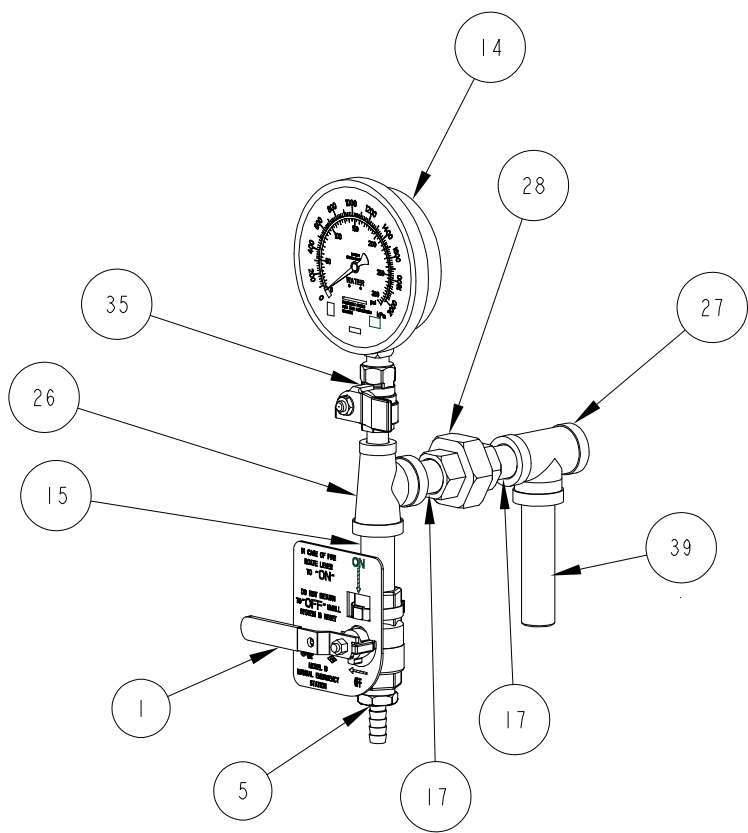

MODEL DDX 4", 6" & 8" BASIC TRIMS
CA-323 P/N 89241293 REV. D



40	PERMA-LOK	PERMA-LOK	NOT SHOWN	A/R
39	98543216	NIPPLE, STEEL, GALV. 1/4" X 3-1/2"	4" & 6" VERSIONS	I
	98543205	NIPPLE, STEEL, GALV. 1/4" X 9"	8" VERSION	
38	98543224	NIPPLE, STEEL, GALV. 1/4" X 4-1/2"	4" & 6" VERSIONS	I
	98543217	NIPPLE, STEEL, GALV. 1/4" X 6"	8" VERSION	
37	9884011A	VALVE, BALL, 1/2 NPTF X 1/2 NPTM		I
36	9101423B	MANIFOLD, 2 X 2 X 1, GRV/THD/THD		I
35	98840237	VALVE, BALL, 1/4" NPTF x 1/4" NPTM		3
34	98840188	VALVE, CHECK, 1/4" NPTM x 1/4" NPTF		I
33	98840147	CHECK VALVE, 1/4, NPT, POPPET TYPE INLINE		I
32	98840145	SWING CHECK VALVE, 1" NPT		I
31	98840103	VALVE, ANGLE, 1/2"		I
30	98840100	VALVE, ANGLE, 2		I
29	98815201	UNION, 1/4, IRON, G.J., GALV.		I
28	98815200	UNION, 1/2, IRON, G.J., GALV.		2
27	98761651	TEE, 1/2X1/2X1/2, GALVANIZED		I
26	98761649	TEE, 1/2X1/4X1/2, GALVANIZED		I
25	98751005	FITTING, MULTIPORT, 3/4x1/2x1/2x1/2x1/2		I
24	98727607	STRAINER, 1/4"		I
23	98614403	PIPE, PLUG, IRON, SQUARE HEAD, 1/4		I
22	98614401	PIPE, PLUG, IRON, SQUARE HEAD, 3/4		I
21	98604406	PIPE, PLUG, IRON, SQUARE HEAD, 1/2		I
20	98543262	NIPPLE, 2X3-1/2, GALVANIZED STEEL		I
19	98543238	NIPPLE, 2XCLOSE, GALVANIZED STEEL		I
18	98543226	NIPPLE, 1/4X1-1/2, GALVANIZED STEEL		2
17	98543223	NIPPLE, 1/2X1-1/2, GALVANIZED STEEL		6
16	98543212	NIPPLE, 1/2XCLOSE, GALVANIZED STEEL		I
15	98543209	NIPPLE, 1/2X2, GALVANIZED STEEL		3
14	98248001	GAUGE, WATER PRESSURE (0-300 PSI)		2
13	98174405	ELBOW, 2", MALL IRON, GALV.		I
12	98174404	ELBOW, 1/4", MALL IRON, GALV.		2
11	98174400	ELBOW, STREET, 1/2", GALV.		I
10	98048022	BUSHING, REDUCER, 3/4X1/2, GALVANIZED		I
9	96920944	HOSE, FLEXIBLE, STAINLESS STEEL, 1/4 NPT X 18 LONG		I
8	96920912	FLEX LINE, 12		I
7	96816906	VALVE, CHECK, MALE 1/2, MALE 1/2		I
6	96606607	TEE, 1/2X1/2X1/4, GALVANIZED		I
5	92056810	CONNECTOR, 3/8" ID TUBE x 1/2" NPT		I
4	92056704	CONNECTOR, ELBOW, 3/8" ID TUBE x 1/2" NPT		2
3	78653800	ASSEMBLY, BALL DRIP, 1/2"		I
2	78653004	ASSEMBLY, VALVE CAUTION STATION, 1/2"		I
1	78653000	ASSEMBLY, MANUAL EMERGENCY STATION		I
ITEM NO.	PART NO.	DESCRIPTION	REMARKS	QTY.

BILL OF MATERIALS

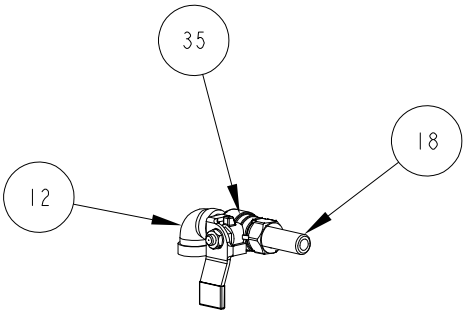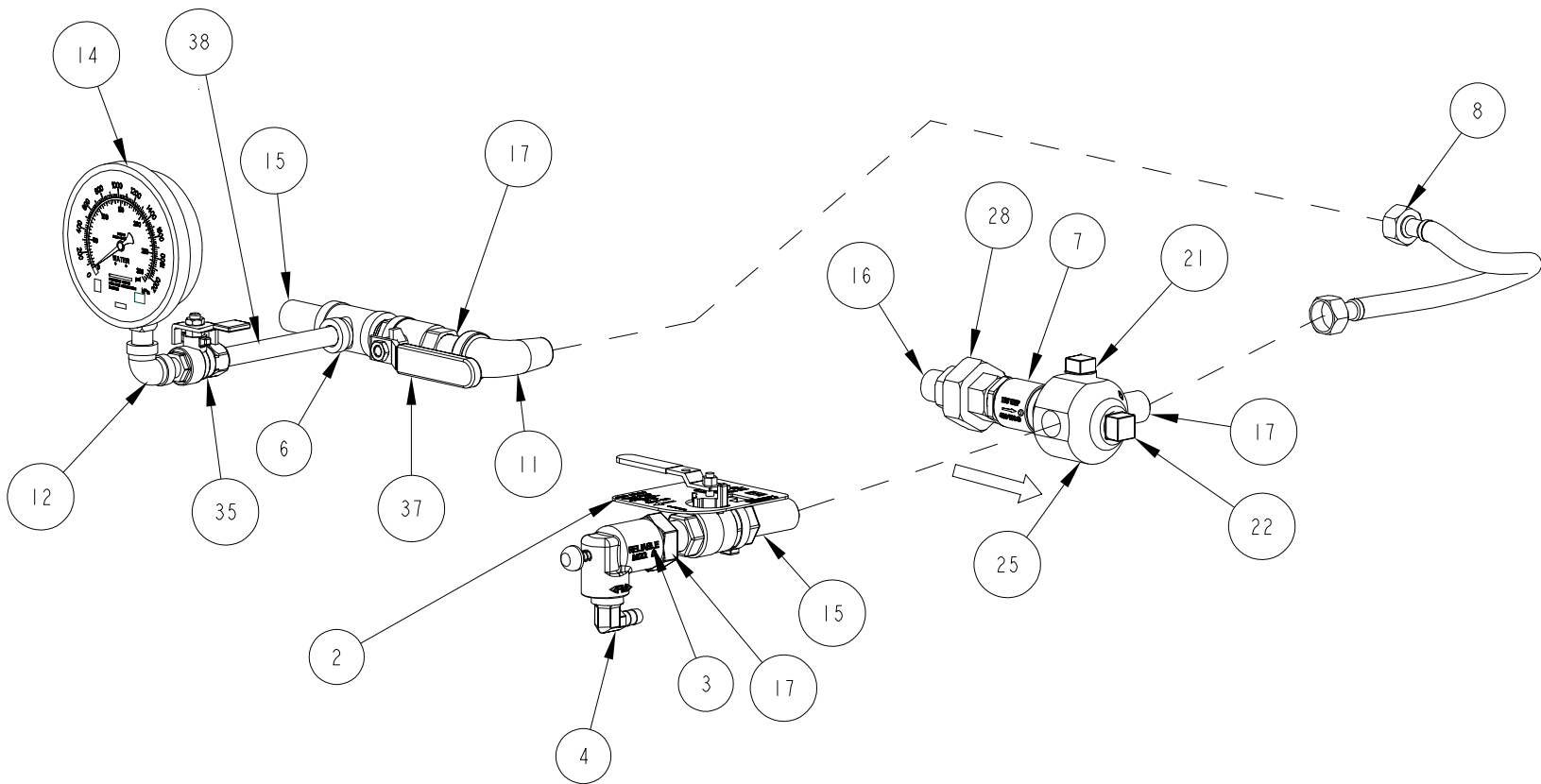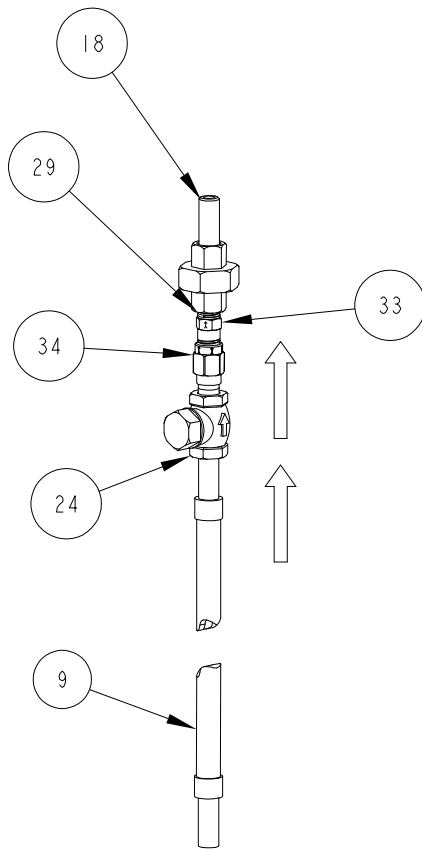

MODEL DDX VALVE WITH STAINLESS STEEL SCREW-IN SEAT

IMPORTANT NOTE: Early generation 4" and 6" DDX valves may incorporate a brass drop-in seat. Prior to ordering replacement parts, confirm the presence of a stainless steel screw-in seat or brass drop-in seat. For replacement parts for valves with brass drop-in seat, please contact Reliable Sprinkler Company Technical Services (techserv@reliablesprinkler.com)

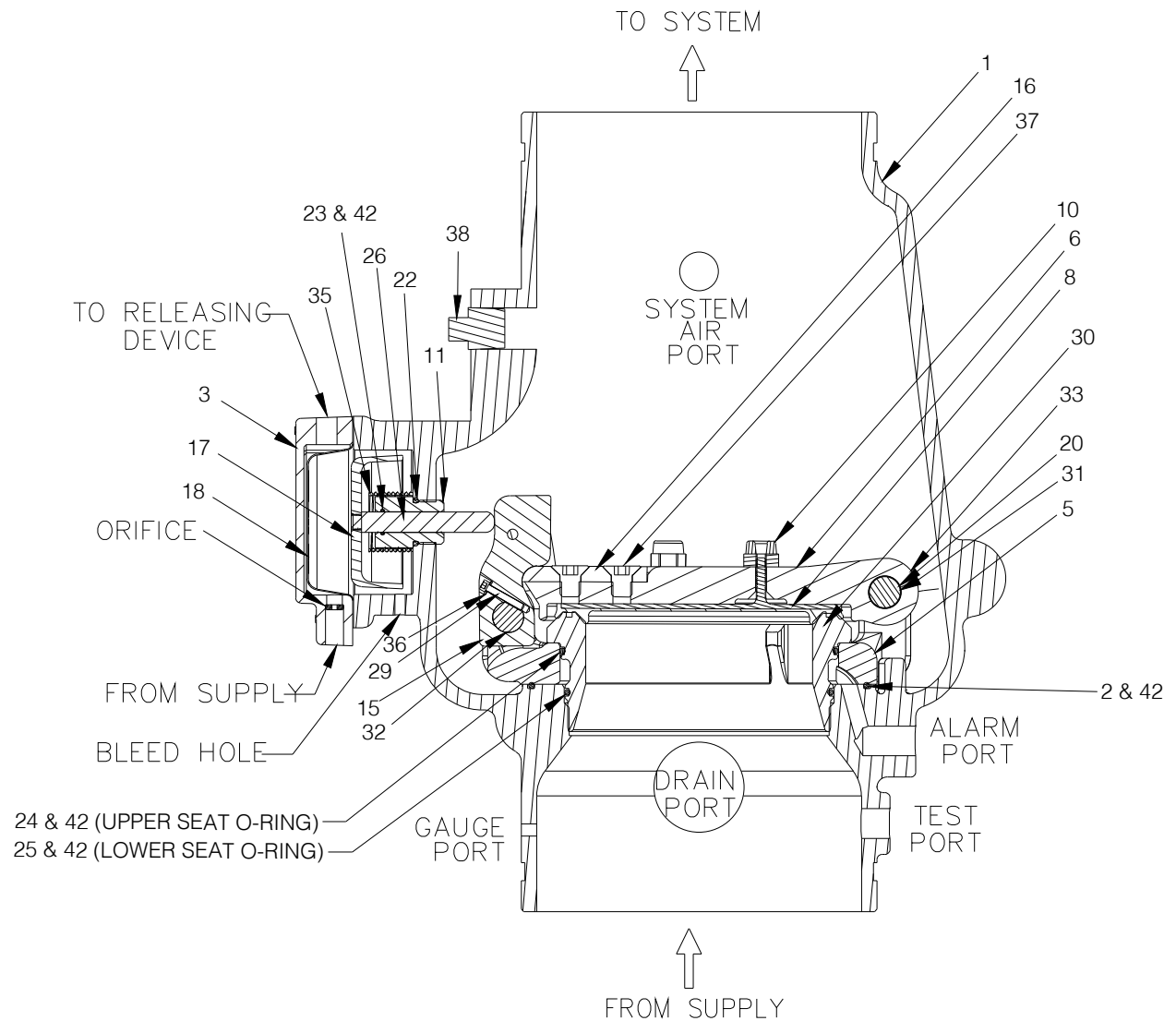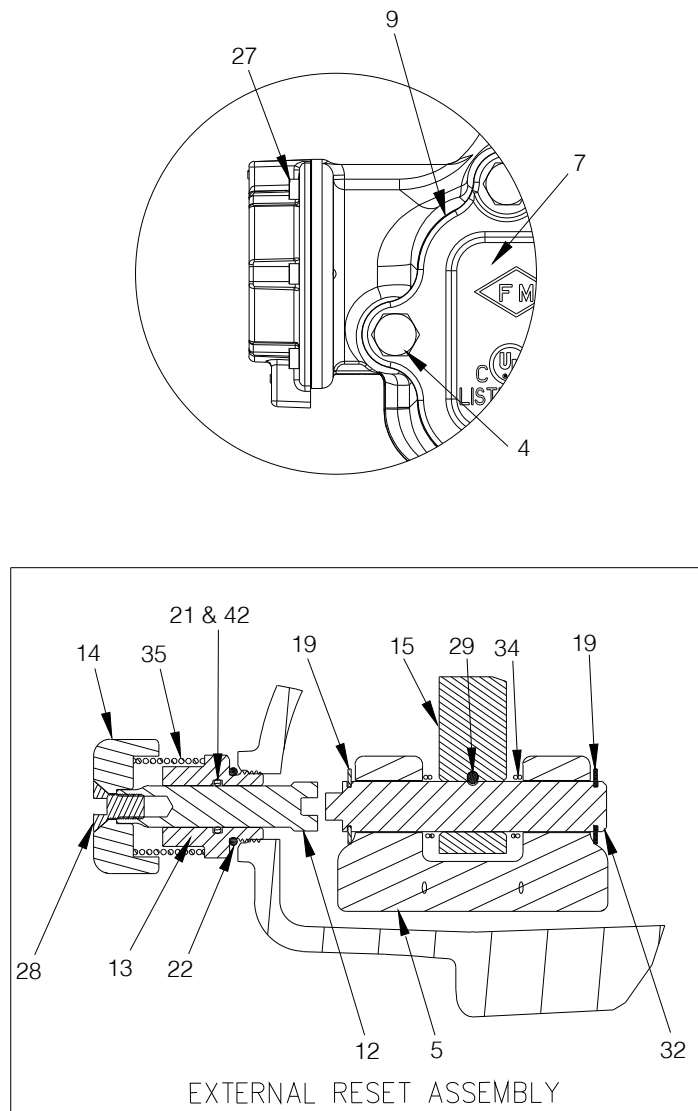

Model DDX (Screw-In Seat Configuration) Deluge Valves Parts List

Item No.	Part No.								Part Description	QTY.	Material
	2" (50mm)	2½" (65mm)	76mm	3" (80mm)	4" (100mm)	165mm	6" (150mm)	8" (200mm)			
1	91006011	91006012	91006023	91006013	91006005	91006027	91006007	91006028	Valve Body Groove/Groove	1	Ductile Iron 65-45-12
	N/A	N/A	N/A	N/A	91006045	N/A	91006067	N/A	Valve Body Flange/Groove		
	N/A	N/A	N/A	N/A	91006035	N/A	91006037	91006039	Valve Body Flange/Flange		
2	N/A	N/A	N/A	N/A	N/A	N/A		95406414	O-ring (Mounting Ring)	1	Buna-N
3	71040416								Pushrod Cover Assembly	1	Ductile Iron 65-45-12 & Brass C360000
4	91106123				N/A	N/A		N/A	Hex Bolt ½"-13 x 1¼"	6	Zinc Plated Steel
	N/A				95606107	N/A		N/A	Hex Bolt ½"-13 x 1½"	6	
	N/A				N/A	91106006		N/A	Hex Bolt ⅝"-11 x 1¾"	6	
	N/A				N/A	N/A		95606110	Hex Bolt ⅝"-11 x 2"	8	
5	91306013				91306014	91306016		91306018	Mounting Ring	1	Stainless Steel CF8 or CF8M
6	91916003				91916014	91916016		91916008	Clapper	1	Stainless Steel CF8 or CF8M
7	92116063				92116064	92116065	92116066	92116068	Access Cover	1	Ductile Iron 65-45-12
8	93416003				93416014	93416016		93416008	Seal Assembly	1	Stainless Steel 304 & EPDM
9	93706003				93706004	93706006		93706008	Access Cover Gasket	1	Buna-N or Neoprene
10	93722000				93722000	N/A		N/A	Bumpstop Assembly	1	Stainless Steel UNS S31600 & EPDM
	N/A				N/A	93722000		N/A		2	
	N/A				N/A	N/A		93722000		3	
11	93916006								Pushrod Guide	1	Acetal
12	93916066								Reset Shaft	1	Brass UNS C36000
13	94106066								Reset Housing	1	Brass UNS C36000
14	94356006								Reset Knob	1	Aluminum 6061
15	94506003				94506004	94506016		94506008	Lever	1	Stainless Steel UNS S17400
16	95006414				94006412	95006410		95006410	Striker	1	Aluminum Bronze C95400
17	95106006								Piston	1	Stainless Steel CF8M
18	95276006								Diaphragm	1	EPDM & Polyester
19	95306267				N/A	N/A		N/A	Retaining Ring, ⅜" Shaft, Lever Pin	2	Stainless Steel 15-7 or 17-7
	N/A				95306267	N/A		N/A	Retaining Ring, ½" Shaft, Lever Pin		
	N/A				N/A	95306269		N/A	Retaining Ring, ⅝" Shaft, Lever Pin		
	N/A				N/A	N/A		95316408	Retaining Ring, ¾" Shaft, Lever Pin		
20	95306268				N/A	N/A		N/A	Retaining Ring, ⅝" Shaft, Hinge Pin	2	Stainless Steel 15-7 or 17-7
	N/A				95306267	95306267		N/A	Retaining Ring, ½" Shaft, Hinge Pin		
	N/A				N/A	N/A		95316408	Retaining Ring, ¾" Shaft, Hinge Pin		
21	95406007								O-Ring, Reset Housing ID	1	Buna-N
22	95406024								O-Ring, Reset Housing & Pushrod Guide OD	2	Buna-N
23	95406407								O-Ring, Pushrod Guide ID	1	Buna-N
24	95406410				95406409	95436126		95406413	O-Ring, Upper Seat	1	Buna-N
25	95406411				95406420	95446226		95406412	O-Ring, Lower Seat	1	Buna-N
26	95506006								Pushrod	1	Stainless Steel UNS S30300
27	95606114								Socket Head Screw, ¼"-20 x ⅝"	6	Steel
28	95606127								Flat Head Socket Cap Screw ⅜"-16 x ¾"	1	Steel
29	95606133				N/A	N/A		N/A	Socket Head Screw #6-32 x ½"	1	Stainless Steel 18-8
	N/A				95606130	95606130		95606130	Socket Head Screw #10-32 x 1"		Stainless Steel UNS S31600
30	96016003				96016014	96016016		96016008	Seat	1	Stainless Steel CF8M
31	96206003				N/A	N/A		N/A	Hinge Pin	1	Stainless Steel UNS S30400
	N/A				96216086	9216086		96206008			Stainless Steel UNS S21800
32	96216003				N/A	N/A		N/A	Lever Pin	1	Stainless Steel UNS S17400
	N/A				96216044	96216047		96216008			Stainless Steel UNS S21800
33	96310003				96906904	96906904		96310008	Clapper Spacer	2	Teflon or Acetal
34	96406003				N/A	N/A		N/A	Lever Spring	1	Stainless Steel UNS S30400
	N/A				96406004	96406005		96406008			Stainless Steel UNS S31600
35	96406906								Piston/ Reset Spring	2	Stainless Steel UNS S31600
36	96906112				N/A	N/A		N/A	Spring Lock Washer, #6	1	Stainless Steel 18-8
	N/A				96906111	96906111		96906111	Spring Lock Washer, #10		Stainless Steel UNS S31600
37	95606140				N/A	N/A		N/A	Flat Head Socket Cap Screw ¼"-20 x ½"	2	Stainless Steel 18-8
	N/A				95606139	N/A		N/A			Stainless Steel UNS S31600
	N/A				N/A	N/A		95606135	Flat Head Socket Cap Screw ½"-13 x ¾"		Stainless Steel UNS S31600
38	98604402								Plug, ½" NPT	1	Steel
39	94616921								Knob Caution Label (Not Shown)	1	Polystyrene
40	91556922								Ball Chain, 1/8" (Not Shown) (Length is in Inches)	6	Nickel Plated Brass
41	91556923								Clamping Link, Ball Chain (Not Shown)	1	
42	699993406								O-Ring Grease, Dupont™ Krytox® GPL-205	A/R	Krytox®