


**OPTIONAL DRAIN TRIM FOR 1-1/2", 2", 2-1/2", 76MM & 3" VERSIONS**  
(ALL DRAIN PLUG & BALL VALVE OPTIONS APPLY)

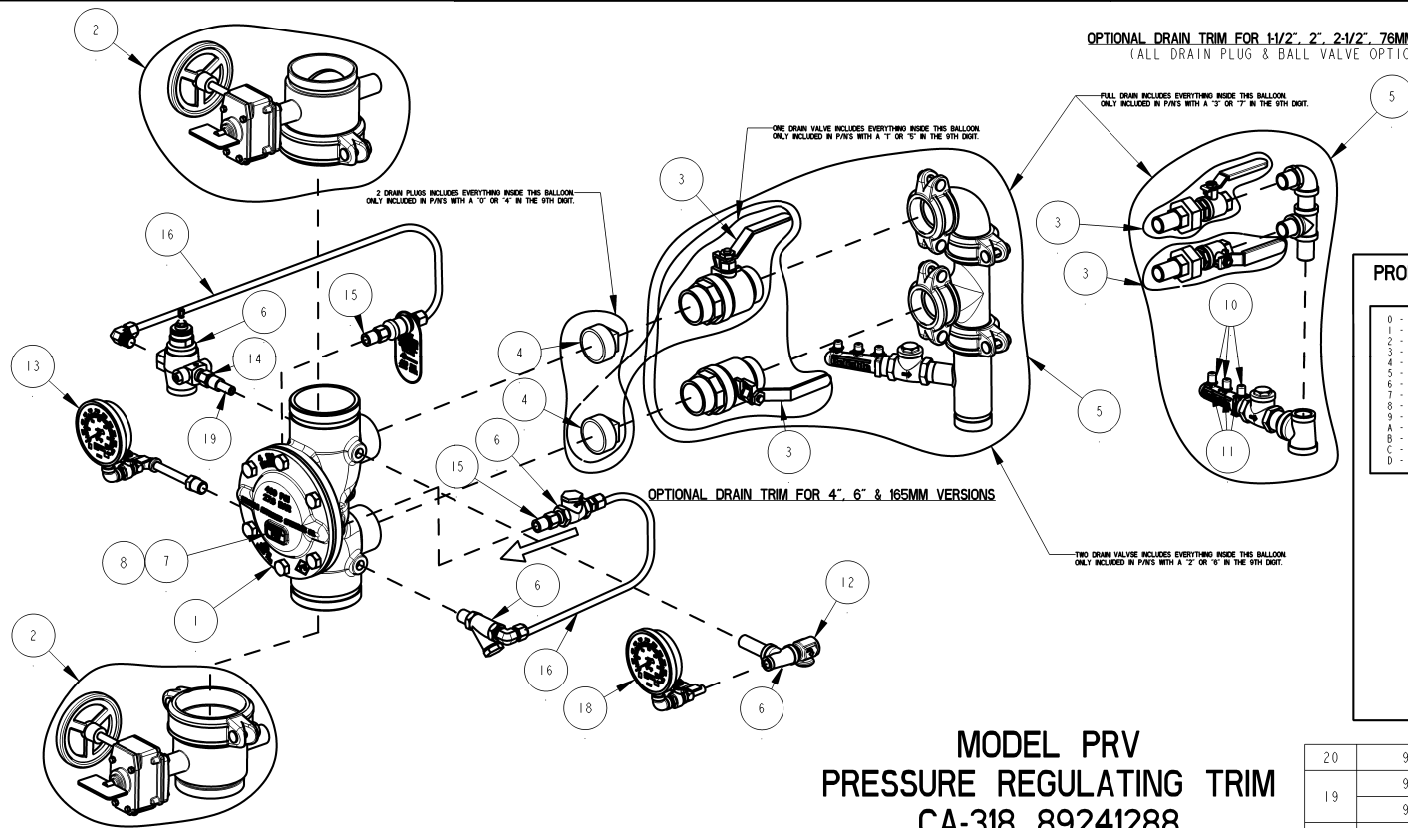

**PRODUCT NUMBER SCHEME**

- 0 - RED, GROOVE/GROOVE
- 1 - RED, FLANGE/FLANGE CLASS 150
- 2 - RED, FLANGE/FLANGE CLASS 300
- 3 - RED, FLANGE/FLANGE PN16
- 4 - RED, FLANGE/FLANGE BS-E
- 5 - RED, THREAD/THREAD NPT
- 6 - RED, THREAD/THREAD ISO 7/1
- 7 - BLACK, GROOVE/GROOVE
- 8 - BLACK, FLANGE/FLANGE CLASS 150
- 9 - BLACK, FLANGE/FLANGE CLASS 300
- A - BLACK, FLANGE/FLANGE PN16
- B - BLACK, FLANGE/FLANGE BS-E
- C - BLACK, THREAD/THREAD NPT
- D - BLACK, THREAD/THREAD ISO 7/1

- 0 - W/O CONTROL VALVE, VERTICAL
- 1 - W/ CONTROL VALVE, VERTICAL
- 2 - W/ 2 CONTROL VALVES, VERTICAL
- 3 - W/ 2 CONTROL VALVES, HORIZONTAL
- 4 - W/O CONTROL VALVE, HORIZONTAL
- 5 - W/O CONTROL VALVE, HORIZONTAL
- 6 - W/ CONTROL VALVE, HORIZONTAL
- 7 - W/ 2 CONTROL VALVES, HORIZONTAL
- 8 - W/ 2 CONTROL VALVES, HORIZONTAL
- 9 - W/ 2 CONTROL VALVES, HORIZONTAL

**6507048400**

- 0 - 1-1/2" VALVE
- 1 - 2" VALVE
- 2 - 2-1/2" VALVE
- 3 - 76MM VALVE
- 4 - 3" VALVE
- 5 - 4" VALVE
- 6 - 6" VALVE
- 7 - 165MM VALVE

- 0 - 185 PSI RELIEF VALVE W/ 300 PSI GAUGES
- 1 - 260 PSI RELIEF VALVE W/ 300 PSI GAUGES
- 2 - 185 PSI RELIEF VALVE W/ 600 PSI GAUGES
- 3 - 260 PSI RELIEF VALVE W/ 600 PSI GAUGES

- 0 - W/ DRAIN PLUGS
- 1 - W/ 1 DRAIN VALVE
- 2 - W/ 2 DRAIN VALVES
- 3 - W/ FULL DRAIN

**MODEL PRV  
PRESSURE REGULATING TRIM  
CA-318 89241288  
ASSEMBLY P/N  
6507048470 REV. L**

**PART NUMBER TABLE**

SIZE	VALVE ASSEMBLY BLACK (ITEM 1)	VALVE ASSEMBLY RED (ITEM 1)	CONTROL VALVE S/A (ITEM 2)	BALL VALVE (DRAIN) (ITEM 3)	PLUG (DRAIN) (ITEM 4)	TRIM, DRAIN (ITEM 5)
1-1/2" GR/GR	6103015507	6103015500	7700030A			
1-1/2" FLG/FLG CLASS 150	6103015508	6103015501	N/A	77000300	98614401	77037003
1-1/2" FLG/FLG CLASS 300	6103015509	6103015502				
1-1/2" FLG/FLG PN16	610301550A	6103015503				
1-1/2" FLG/FLG BS-E	610301550B	6103015504				
1-1/2" THD/THD NPT	610301550C	6103015505				
1-1/2" THD/THD ISO 7/1	610301550D	6103015506				
2" GR/GR	6103020507	6103020500				
2" FLG/FLG CLASS 150	6103020508	6103020501	N/A	77000302	95200126	77037004
2" FLG/FLG CLASS 300	6103020509	6103020502				
2" FLG/FLG PN16	610302050A	6103020503				
2" FLG/FLG BS-E	610302050B	6103020504				
2" THD/THD NPT	610302050C	6103020505				
2" THD/THD ISO 7/1	610302050D	6103020506				
2-1/2" GR/GR	6103025507	6103025500				
2-1/2" FLG/FLG CLASS 150	6103025508	6103025501	N/A	77000299	95200126	77037004
2-1/2" FLG/FLG CLASS 300	6103025509	6103025502				
2-1/2" FLG/FLG PN16	610302550A	6103025503				
2-1/2" FLG/FLG BS-E	610302550B	6103025504				
2-1/2" THD/THD NPT	610302550C	6103025505				
2-1/2" THD/THD ISO 7/1	610302550D	6103025506				
76MM GR/GR	6103076507	6103076500				
3" GR/GR	6103030507	6103030500	77000303			
3" FLG/FLG CLASS 150	6103030508	6103030501	N/A	77000304	95206106	77037002
3" FLG/FLG CLASS 300	6103076509	6103076502				
3" FLG/FLG PN16	610303050A	6103030503				
3" FLG/FLG BS-E	610303050B	6103030504				
3" THD/THD NPT	610303050C	6103030505				
3" THD/THD ISO 7/1	610303050D	6103030506				
4" GR/GR	6103040507	6103040500				
4" FLG/FLG CLASS 150	6103040508	6103040501	N/A	77000306	95206106	77037002
4" FLG/FLG CLASS 300	6103040509	6103040502				
4" FLG/FLG PN16	610304050A	6103040503				
4" FLG/FLG BS-E	610304050B	6103040504				
6" GR/GR	6103060507	6103060500	77000306	98840110	95206106	77037002
6" FLG/FLG CLASS 150	6103060508	6103060501	N/A	77000306	95206106	77037002
6" FLG/FLG CLASS 300	6103060509	6103060502				
6" FLG/FLG PN16	610306050A	6103060503				
6" FLG/FLG BS-E	610306050B	6103060504				
165MM GR/GR	6103065507	6103065500	N/A			

20	95516918	LOCTITE 271, THREAD LOCKER	NOT SHOWN	A/R
19	98768201	PICKUP TUBE, 3-1/2"	6" ONLY	I
	98768200	PICKUP TUBE, 1-1/2"	4" ONLY	
18	98248001	GAUGE, WATER PRESSURE (0-300 PSI)		I
17	89097903	THREAD SEALANT	NOT SHOWN	A/R
16	98768010	COPPER TUBE, 1/2"	40 IN	A/R
15	98580015	ORIFICE, RESTRICTING, 1/2" NPT, .125 ORIF.	6"	2
	98580023	ORIFICE, RESTRICTING, 1/2" NPT, .093 ORIF.	4"	
	98580022	ORIFICE, RESTRICTING, 1/2" NPT, .078 ORIF.	3"	
	98580022	ORIFICE, RESTRICTING, 1/2" NPT, .078 ORIF.	2-1/2"	
	98580017	ORIFICE, RESTRICTING, 1/2" NPT, .062 ORIF.	2"	
	98580017	ORIFICE, RESTRICTING, 1/2" NPT, .062 ORIF.	1-1/2"	
	98580018	ORIFICE, RESTRICTING, 1/2" NPT, .188 ORIF.	6"	
14	98580015	ORIFICE, RESTRICTING, 1/2" NPT, .125 ORIF.	4"	I
	98580024	ORIFICE, RESTRICTING, 1/2" NPT, .109 ORIF.	3"	
	98580024	ORIFICE, RESTRICTING, 1/2" NPT, .109 ORIF.	2-1/2"	
	98580023	ORIFICE, RESTRICTING, 1/2" NPT, .093 ORIF.	2"	
	98580022	ORIFICE, RESTRICTING, 1/2" NPT, .078 ORIF.	1-1/2"	
13	98248005	GAUGE, WATER PRESSURE (0-600 PSI)		I
	98248001	GAUGE, WATER PRESSURE (0-300 PSI)		
12	6501000004	RELIEF VALVE, 260 PSIG		I
	6501000002	RELIEF VALVE, 185 PSIG		
11	95306255	CLAMP, HOSE, 1/2" CONSTANT TENSION, ZINC		3
10	99050906	END CAP, PVC, 1/2"		3
9	94616961	NAMEPLATE		I
8	94617016	PLATE		I
7	94616999	ADHESIVE, BACKING PAD		I
6	77037024	BASE TRIM, PRESSURE REGULATING		I
5	SEE PART NUMBER TABLE	TRIM, SUB-ASSY, DRAIN		I
4		PLUG (DRAIN)		A/R
3		BALL VALVE (DRAIN)		A/R
2		SUBASSEMBLY, CONTROL VALVE		A/R
1		ASSEMBLY, VALVE, DDV		I
<b>ITEM NO.</b>	<b>PART NO.</b>	<b>DESCRIPTION</b>	<b>REMARKS</b>	<b>QTY.</b>

**BILL OF MATERIALS**