

Product Spotlight


Flexible Drops



Flexible Sprinkler Hose with Fittings

RASCOFLEX® Sprinkler Connections


Seismic Expansion Joints

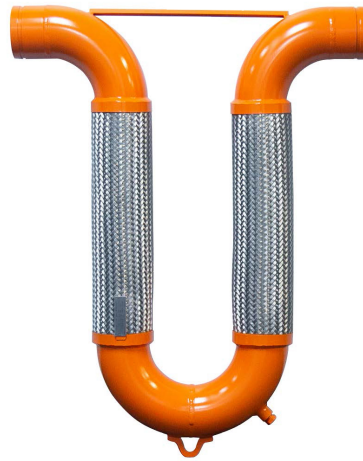

Grooved Connections for Sizes 1" through 10"

Reliable® Model RLP RASCOLOOP Seismic Expansion Joint

Flexible Drain Hoses

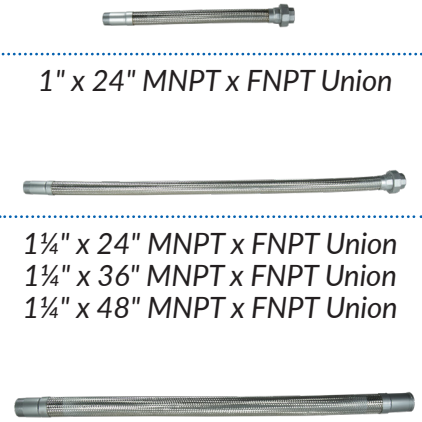

1" x 24" MNPT x FNPT Union

1¼" x 24" MNPT x FNPT Union
1¼" x 36" MNPT x FNPT Union
1¼" x 48" MNPT x FNPT Union

2" x 48" MNPT x Groove

Reliable® Streamline™ Drain Hoses

OS&Y & Check Valves



Resilient Seated OS&Y Gate Valves: FxF, FxG or GxG

Non-Rising Stem Gate Valve

Wall & Vertical Indicator Posts

Reliable® Iron Valves, OS&Y Valves, Check Valves, PIV Valves and Posts

Butterfly Valves

Grooved Tapped Butterfly Valve

- 363 psi rated
- 2" through 10"




Reliable® REL363GT & REL363GTC



- 300 psi rated
- 1" - 2w½"
- Grooved or Threaded

Reliable® RBV Series Bronze Butterfly Valves

Trim Valves

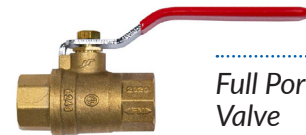

Full Port Ball Valve



Auxiliary Drain Valve



Globe Valve

Reliable® Ball Valves, Aux Drain Valves, and Globe Valves

Grooved

A full line of pipe connection products



Reliable® Grooved Couplings and Fittings

FDC Equipment



Female Thread x Male Thread

Grooved x Male Thread



2 1/2" cap



1 1/2" cap

Fire Department Connections and Accessories

Spare Sprinkler Cabinets



Fits 3 to 36 Sprinklers and 1 Wrench

Reliable® Model RHB1 Sprinkler Cabinets

Test and Drains



Model TD Test & Drain Valve 1" with optional relief valve kit; threaded inlet



Model TD Test & Drain Valve 2" with optional relief valve kit; grooved inlet

Reliable® Model TD Test and Drain Valve

Brass Extension Nipples



1/2" Brass Extensions



3/4" Brass Extensions

Machined from Forged Brass Bar Stock

Wet System Air Vent



AAV Automatic Air Vent with 1/2" inlet and outlet

Reliable® Model AAV Automatic Air Vent

Aux Condensate Drain



Auxiliary Condensate Drain used in dry pipe and preaction systems

Reliable® Model ACD Dry System Auxiliary Condensate Drain