

## PRINTED COVERPLATES


• See Bulletin 203



Slate Grey



Warm Maple

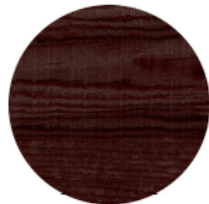

Dark Walnut



Silver Birch

**Note: Please see Bulletin 203 for additional finishes**

Part Number	Short Code	Temperature		Finish	List Price
<b>MODEL G6 PRINTED COVERPLATES</b>					
688721139A		135°F	57°C	Custom Ink	C\$ 81.81
688721139B		135°F	57°C	White Wash	C\$ 81.81
688721139C		135°F	57°C	Silver Birch	C\$ 81.81
688721139D		135°F	57°C	Beige Birch	C\$ 81.81
688721139E		135°F	57°C	Weathered Grey	C\$ 81.81
688721139F		135°F	57°C	Slate Grey	C\$ 81.81
688721139G		135°F	57°C	Golden Pine	C\$ 81.81
688721139H		135°F	57°C	Red Oak	C\$ 81.81
688721139J		135°F	57°C	Red Cherry	C\$ 81.81
688721139K		135°F	57°C	Warm Maple	C\$ 81.81
688721139M		135°F	57°C	Dark Walnut	C\$ 81.81
688721139N		135°F	57°C	Espresso	C\$ 81.81
688721139P		135°F	57°C	Rustic Beige	C\$ 81.81
<b>MODEL RFS42 PRINTED COVERPLATES</b>					
688723139A		135°F	57°C	Custom Ink	C\$ 82.56
688723139B		135°F	57°C	White Wash	C\$ 82.56
688723139C		135°F	57°C	Silver Birch	C\$ 82.56
688723139D		135°F	57°C	Beige Birch	C\$ 82.56
688723139E		135°F	57°C	Weathered Grey	C\$ 82.56
688723139F		135°F	57°C	Slate Grey	C\$ 82.56
688723139G		135°F	57°C	Golden Pine	C\$ 82.56
688723139H		135°F	57°C	Red Oak	C\$ 82.56
688723139J		135°F	57°C	Red Cherry	C\$ 82.56
688723139K		135°F	57°C	Warm Maple	C\$ 82.56
688723139M		135°F	57°C	Dark Walnut	C\$ 82.56
688723139N		135°F	57°C	Espresso	C\$ 82.56
688723139P		135°F	57°C	Rustic Beige	C\$ 82.56
<b>MODEL G5 PRINTED COVERPLATES</b>					
688727139A		135°F	57°C	Custom Ink	C\$ 76.70
688727139B		135°F	57°C	White Wash	C\$ 76.70
688727139C		135°F	57°C	Silver Birch	C\$ 76.70
688727139D		135°F	57°C	Beige Birch	C\$ 76.70
688727139E		135°F	57°C	Weathered Grey	C\$ 76.70
688727139F		135°F	57°C	Slate Grey	C\$ 76.70
688727139G		135°F	57°C	Golden Pine	C\$ 76.70
688727139H		135°F	57°C	Red Oak	C\$ 76.70
688727139J		135°F	57°C	Red Cherry	C\$ 76.70
688727139K		135°F	57°C	Warm Maple	C\$ 76.70
688727139M		135°F	57°C	Dark Walnut	C\$ 76.70
688727139N		135°F	57°C	Espresso	C\$ 76.70
688727139P		135°F	57°C	Rustic Beige	C\$ 76.70
688727169A		165°F	74°C	Custom Ink	C\$ 76.70
688727169B		165°F	74°C	White Wash	C\$ 76.70
688727169C		165°F	74°C	Silver Birch	C\$ 76.70
688727169D		165°F	74°C	Beige Birch	C\$ 76.70
688727169E		165°F	74°C	Weathered Grey	C\$ 76.70
688727169F		165°F	74°C	Slate Grey	C\$ 76.70
688727169G		165°F	74°C	Golden Pine	C\$ 76.70
688727169H		165°F	74°C	Red Oak	C\$ 76.70
688727169J		165°F	74°C	Red Cherry	C\$ 76.70
688727169K		165°F	74°C	Warm Maple	C\$ 76.70
688727169M		165°F	74°C	Dark Walnut	C\$ 76.70
688727169N		165°F	74°C	Espresso	C\$ 76.70
688727169P		165°F	74°C	Rustic Beige	C\$ 76.70