

PRINTED COVERPLATES


- See Bulletin 203



Slate Grey



Warm Maple

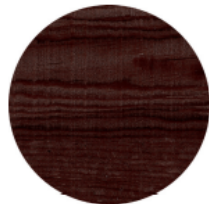

Dark Walnut



Silver Birch

**Note: Please see
Bulletin 203 for
additional finishes**

Part Number	Short Code	Temperature		Finish	List Price
MODEL G6 PRINTED COVERPLATES					
688721139A		135°F	57°C	Custom Ink	S\$ 102.96
688721139B		135°F	57°C	White Wash	S\$ 99.26
688721139C		135°F	57°C	Silver Birch	S\$ 99.26
688721139D		135°F	57°C	Beige Birch	S\$ 99.26
688721139E		135°F	57°C	Weathered Grey	S\$ 99.26
688721139F		135°F	57°C	Slate Grey	S\$ 99.26
688721139G		135°F	57°C	Golden Pine	S\$ 99.26
688721139H		135°F	57°C	Red Oak	S\$ 99.26
688721139J		135°F	57°C	Red Cherry	S\$ 99.26
688721139K		135°F	57°C	Warm Maple	S\$ 99.26
688721139M		135°F	57°C	Dark Walnut	S\$ 99.26
688721139N		135°F	57°C	Espresso	S\$ 99.26
688721139P		135°F	57°C	Rustic Beige	S\$ 99.26
MODEL RFS42 PRINTED COVERPLATES					
688723139A		135°F	57°C	Custom Ink	S\$ 103.92
688723139B		135°F	57°C	White Wash	S\$ 100.16
688723139C		135°F	57°C	Silver Birch	S\$ 100.16
688723139D		135°F	57°C	Beige Birch	S\$ 100.16
688723139E		135°F	57°C	Weathered Grey	S\$ 100.16
688723139F		135°F	57°C	Slate Grey	S\$ 100.16
688723139G		135°F	57°C	Golden Pine	S\$ 100.16
688723139H		135°F	57°C	Red Oak	S\$ 100.16
688723139J		135°F	57°C	Red Cherry	S\$ 100.16
688723139K		135°F	57°C	Warm Maple	S\$ 100.16
688723139M		135°F	57°C	Dark Walnut	S\$ 100.16
688723139N		135°F	57°C	Espresso	S\$ 100.16
688723139P		135°F	57°C	Rustic Beige	S\$ 100.16
MODEL G5 PRINTED COVERPLATES					
688727139A		135°F	57°C	Custom Ink	S\$ 96.53
688727139B		135°F	57°C	White Wash	S\$ 93.05
688727139C		135°F	57°C	Silver Birch	S\$ 93.05
688727139D		135°F	57°C	Beige Birch	S\$ 93.05
688727139E		135°F	57°C	Weathered Grey	S\$ 93.05
688727139F		135°F	57°C	Slate Grey	S\$ 93.05
688727139G		135°F	57°C	Golden Pine	S\$ 93.05
688727139H		135°F	57°C	Red Oak	S\$ 93.05
688727139J		135°F	57°C	Red Cherry	S\$ 93.05
688727139K		135°F	57°C	Warm Maple	S\$ 93.05
688727139M		135°F	57°C	Dark Walnut	S\$ 93.05
688727139N		135°F	57°C	Espresso	S\$ 93.05
688727139P		135°F	57°C	Rustic Beige	S\$ 93.05
688727169A		165°F	74°C	Custom Ink	S\$ 96.53
688727169B		165°F	74°C	White Wash	S\$ 93.05
688727169C		165°F	74°C	Silver Birch	S\$ 93.05
688727169D		165°F	74°C	Beige Birch	S\$ 93.05
688727169E		165°F	74°C	Weathered Grey	S\$ 93.05
688727169F		165°F	74°C	Slate Grey	S\$ 93.05
688727169G		165°F	74°C	Golden Pine	S\$ 93.05
688727169H		165°F	74°C	Red Oak	S\$ 93.05
688727169J		165°F	74°C	Red Cherry	S\$ 93.05
688727169K		165°F	74°C	Warm Maple	S\$ 93.05
688727169M		165°F	74°C	Dark Walnut	S\$ 93.05
688727169N		165°F	74°C	Espresso	S\$ 93.05
688727169P		165°F	74°C	Rustic Beige	S\$ 93.05